


# Manifold rail VABM-C8-12E-G14-18-M1-L

Part number: 1361874

FESTO

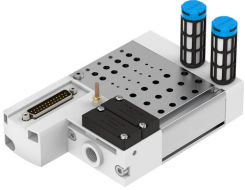

## Data sheet

Feature	Value
Width dimension	12 mm
Type code	VABM
Max. no. of valve positions	18
Corrosion resistance class (CRC)	0 - No corrosion stress
Max. tightening torque for valve mounting	0.6 Nm
Max. tightening torque for wall mounting	5 Nm
Product weight	1195 g
Pneumatic connection 1	G1/4
Pneumatic connection 3	G1/4
Pneumatic connection 5	G1/4
Note on materials	Free of copper and PTFE RoHS-compliant
Manifold rail material	Wrought aluminum alloy