


# Quick coupling EAMC-67-62-24-32

Part number: 1485796

FESTO

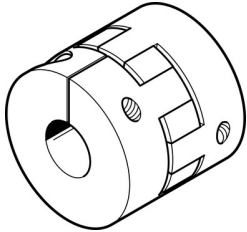

## Data sheet

Feature	Value
Diameter of holder 1	24 mm
Diameter of holder 2	32 mm
Size	67
Nominal length	62 mm
Type code	EAMC
Mounting position	Any
Max. rotational speed	4500 1/min
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 °C ... 60 °C
Mass moment of inertia	280 kgmm <sup>2</sup>
Transferable torque	143 Nm
Product weight	428 g
Note on materials	RoHS-compliant