


Plug socket with cable KMEB-1-24-2.5-LED

Part number: 151688

FESTO

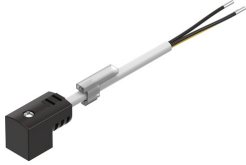

Data sheet

Feature	Value
Type code	KMEB
Switching position indication	LED
Type of mounting	On air solenoid valve with M2.5 central screw
Mounting position	Any
Product weight	125 g
Electrical connection	3-pin Socket, angled Form C as per DIN EN 175301-803
Nominal operating voltage DC	24 V
Protective earth connection	Available
Cable length	2.5 m
Cable diameter	5.2 mm
Cable design	3 x 0.5 mm ²
Degree of protection	IP65 as per IEC 60529
Ambient temperature	-20 °C ... 80 °C
CE marking (see declaration of conformity)	As per EU RoHS directive
Corrosion resistance class (CRC)	1 - Low corrosion stress
Material of cable sheath	PVC
Housing material	PA66-GF30
Material of pin contacts	Bronze