


# Non return valve HB-1/8-QS-8

Part number: 153453

FESTO

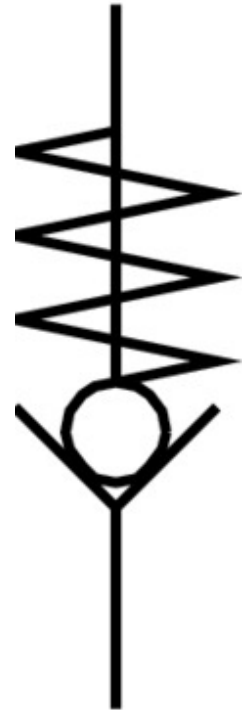

## Data sheet

| Feature                                  | Value  |
|--|--|
| Type code                                | HB   |
| Valve function                           | Non-return function  |
| Pneumatic connection 1                   | QS-8   |
| Pneumatic connection 2                   | R1/8   |
| Type of mounting                         | Screw-in   |
| Standard nominal flow rate               | 314 l/min  |
| Operating pressure                       | -1 bar ... 10 bar  |
| Ambient temperature                      | 0 °C ... 60 °C   |
| Housing material                         | Brass, nickel-plated   |
| Operating medium                         | Compressed air as per ISO 8573-1:2010 [7:-:-]                      |
| Symbol                                   | 00991455   |
| Min. differential pressure, opening      | 0.1 bar  |
| Min. differential pressure, closing      | 0.2 bar  |
| Information on operating and pilot media | Operation with oil lubrication possible (required for further use) |
| Product weight                           | 22 g   |
| Note on materials                        | RoHS-compliant   |