


# Non return valve HA-3/8-QS-10

Part number: 153456

FESTO

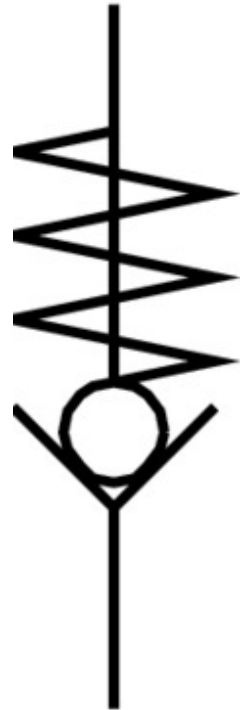

## Data sheet

Feature	Value
Type code	HA
Valve function	Non-return function
Pneumatic connection 1	R3/8
Pneumatic connection 2	QS-10
Type of mounting	Screw-in
Standard nominal flow rate	1740 l/min
Operating pressure	-1 bar ... 10 bar
Ambient temperature	0 °C ... 60 °C
Housing material	Aluminum, anodized
Housing colour	Silver
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Symbol	00991455
Min. differential pressure, opening	0.1 bar
Min. differential pressure, closing	0.2 bar
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Product weight	47 g
Note on materials	RoHS-compliant