


# Non return valve HB-1/2-QS-12

Part number: 153461

FESTO

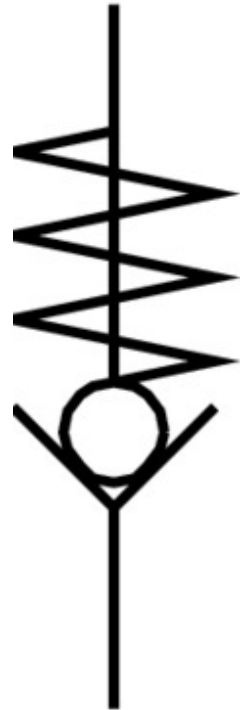

## Data sheet

Feature	Value
Type code	HB
Valve function	Non-return function
Pneumatic connection 1	QS-12
Pneumatic connection 2	R1/2
Type of mounting	Screw-in
Standard nominal flow rate	2206 l/min
Operating pressure	-1 bar ... 10 bar
Ambient temperature	0 °C ... 60 °C
Housing material	Aluminum, anodized
Housing colour	Silver
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Symbol	00991455
Min. differential pressure, opening	0.1 bar
Min. differential pressure, closing	0.2 bar
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Product weight	69 g
Note on materials	RoHS-compliant