


Vacuum filter VAF-PK-6

Part number: 160239

FESTO

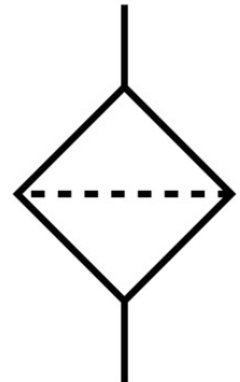

Data sheet

Feature	Value
Nominal width	4.6 mm
Type code	VAF
Mounting position	Any
Grade of filtration	50 µm
Symbol	00991483
Operating pressure	-0.95 bar ... 0 bar
Information on operating pressure	Only for use in open vacuum systems
Flow rate at negative pressure = -0.75 bar	210 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Ambient temperature	0 °C ... 40 °C
Product weight	10 g
Type of mounting	Line installation
Pneumatic connection	PK-6 with union nut
Material of union nut	POM
Note on materials	RoHS-compliant
Compressed air filter material	Fabric PA
Housing material	PA
Ejector pulse suitability	≤8 bar