


Sub-base PAML-CP-186-HP3-G2

Part number: 1629298

FESTO

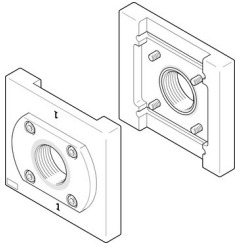

Data sheet

| Feature | Value |
|--------------------------------------------|----------------------------------------------|
| Size | 186 |
| Nominal width DN | 54 |
| Type code | PAML |
| Series | L |
| Operating pressure | 0 MPa ... 5 MPa |
| Operating pressure | 0 bar ... 50 bar |
| CE marking (see declaration of conformity) | as per EU pressure equipment directive |
| Operating medium | Compressed air as per ISO 8573-1:2010 [-:--] |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress |
| Storage temperature | -10 °C ... 60 °C |
| For use in the food industry | See supplementary material information |
| Temperature of medium | 5 °C ... 60 °C |
| Ambient temperature | 5 °C ... 60 °C |
| Product weight | 4400 g |
| Pneumatic connection 1 | G2 |
| Pneumatic connection 2 | G2 |
| Note on materials | RoHS-compliant |
| Material of sub-base | Wrought aluminum alloy |
| Seals material | NBR |
| Material of screws | Stainless steel |