


Branching module FRM-3/8-D-MIDI

Part number: 164952

FESTO

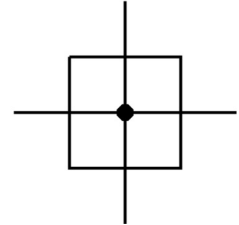

Data sheet

Feature	Value
Type code	FRM
Mounting position	Any
Structural design	Branching module
Symbol	00991510
Operating pressure	0 bar ... 16 bar
Standard nominal flow rate in main flow direction 1 -> 2	6700 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-] Inert gas
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-10 °C ... 60 °C
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [7:-:-] Inert gas
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	522 g
Pneumatic connection 1	G3/8
Pneumatic connection 2	G3/8
Pneumatic connection 3	G1/2
Pneumatic connection 4	G1/4
Note on materials	Free of copper and PTFE RoHS-compliant
Housing material	Die-cast aluminum