 



Flat cylinder EZH-2,5/9-20-B

Part number: 164992

FESTO

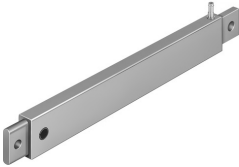

Data sheet

Feature	Value
Stroke	20 mm
Piston diameter	6 mm Equivalent diameter
Type code	EZH
Cushioning	No cushioning
Mounting position	Any
Mode of operation	Single-acting Pushing
Structural design	Piston Rectangular piston rod
Position sensing	None
Symbol	00991200
Protection against torsion/guide	Rectangular piston rod
Operating pressure	2.8 bar ... 6 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Ambient temperature	0 °C ... 60 °C
Theoretical force at 6 bar, advancing	10 N
Theoretical min. spring return force	2.8 N
Theoretical max. spring return force	4.4 N
Product weight	17 g
Type of mounting	With cross hole
Pneumatic connection	Barbed fitting PK-3
Cover material	Aluminum
Seals material	TPE-U(PU)
Housing material	Aluminum
Piston rod material	Copper alloy Nickel-plated