


Compressed air filter LF-3/4-D-5M-MIDI-NPT

Part number: 173698

FESTO

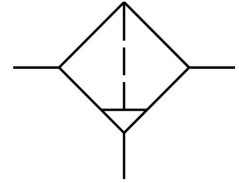

Data sheet

Feature	Value
Size	Midi
Type code	LF
Series	D
Mounting position	Vertical
Grade of filtration	5 µm
Condensate drain	Manual, non-detenting
Max. condensate volume	43 ml
Bowl guard	Metal bowl guard
Symbol	00991519
Operating pressure	0 bar ... 16 bar
Standard nominal flow rate	2000 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [-:9:-] Inert gas
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-10 °C ... 60 °C
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [6:8:4] Inert gas
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Type of mounting	Optionally: Line installation With mounting bracket
Pneumatic connection 1	3/4 NPT
Pneumatic connection 2	3/4 NPT
Note on materials	RoHS-compliant
Compressed air filter material	PE
Housing material	Die-cast zinc
Material of bowl	PC