


Clevis flange SNCS-100

Part number: 174402

FESTO

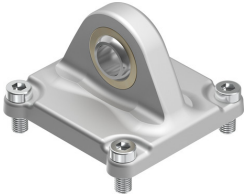

Data sheet

Feature	Value
Size	100
Type code	SNCS
Based on norm	ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Ambient temperature	-40 °C ... 150 °C
Product weight	683 g
Note on materials	RoHS-compliant
Mounting material	Wrought aluminum alloy
Rod end bearing material	Steel PTFE
Material of screws	Steel Galvanized