


Clevis flange SNCL-125

Part number: 174410

FESTO

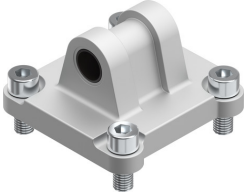

Data sheet

Feature	Value
Size	125
Type code	SNCL
Based on norm	ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance class (CRC)	1 - Low corrosion stress
Ambient temperature	-40 °C ... 90 °C
Product weight	1135 g
Note on materials	Free of copper and PTFE RoHS-compliant
Mounting material	Die-cast aluminum
Material of bearing	Polymer
Material of screws	Steel Galvanized