
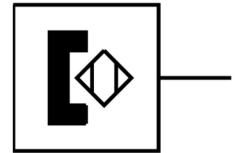


Position sensor SMH-S1-HGR10

Part number: 175712

FESTO

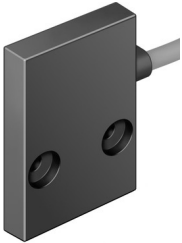

Data sheet

| Feature | Value |
|--|----------------------------------|
| Type code | SMH-S1 |
| Design | for pneumatic gripper |
| Symbol | 00991630 |
| CE marking (see declaration of conformity) | As per EU EMC directive |
| Note on materials | Free of copper and PTFE |
| Measuring principle | Magnetic Hall |
| Ambient temperature | 5 °C ... 60 °C |
| Short-circuit protection | no |
| Reverse polarity protection | no |
| Electrical connection | 4-pin Cable with plug M8x1 |
| Cable length | 0.5 m |
| Material of cable sheath | TPE-U(PUR) |
| Type of mounting | Screwed on to pneumatic gripper |
| Product weight | 20 g |
| Housing material | PA |
| Degree of protection | IP65 |