


Proximity sensor SMPO-8E

Part number: 178563

FESTO

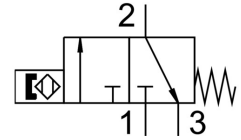

Data sheet

Feature	Value
Type code	SMPO
Design	for T-slot
Symbol	00991600
Explosion prevention and protection	Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Note on materials	Free of copper and PTFE RoHS-compliant
Measuring principle	Magnetic
Operating pressure	2 bar ... 8 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [6:4:4]
Information on operating and pilot media	Operation with oil lubrication not possible
Ambient temperature	-15 °C ... 60 °C
Reproducibility of switching value	+/- 0.2 mm
On time	22 ms
Switch-off time	52 ms
Type of mounting	With through-hole With accessories Can be inserted in slot from above
Valve function	3/2
Pneumatic connection	M5
Product weight	11 g
Housing material	Aluminum PA Anodized High-alloy stainless steel
Switching status indication	Optical
Degree of protection	IP65