


# Connection block VIGM-04-D-3

Part number: 18835

FESTO

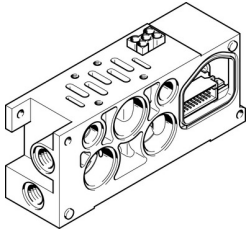

## Data sheet

Feature	Value
Type code	VIGM
Based on norm	ISO 5599-2
Max. no. of valve positions	1
Operating pressure	-0.9 bar ... 16 bar
Certification	UL - Recognized (OL)
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Temperature of medium	-10 °C ... 60 °C
Degree of protection	IP65
Ambient temperature	-10 °C ... 60 °C
Sub-base mounting type	With through-hole
Pneumatic connection 1	G1
Pneumatic connection 2	G1/2
Pneumatic connection 3	G1
Pneumatic connection 4	G1/2
Pneumatic connection 5	G1
Note on materials	RoHS-compliant
Material of sub-base	Die-cast aluminum