


Vacuum suction cup holder ESH-HE-5-G1/4

FESTO

Part number: 189257

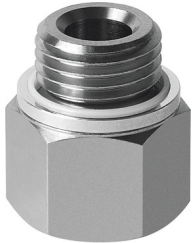

Data sheet

Feature	Value
Nominal width	7 mm
Volume	1.227 cm ³
Type code	ESH
Mounting position	Vertical
Structural design	Vacuum connection at top
Classification of suction cup holder	Size 5
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
Corrosion resistance class (CRC)	1 - Low corrosion stress
Ambient temperature	-10 °C ... 60 °C
Product weight	24 g
Type of mounting	With external thread Via vacuum connection
Suction cup mounting	M10
Vacuum connection	G1/4
Note on materials	RoHS-compliant
Seals material	Wrought aluminum alloy NBR POM Steel
Retaining bracket material	Tempered steel