


Power supply module VABF-C8-12-P3A5-QX

Part number: 1894888

FESTO

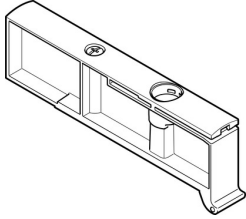

Data sheet

Feature	Value
Type code	VABF
Operating pressure	<8 bar
Corrosion resistance class (CRC)	0 - No corrosion stress
Temperature of medium	-5 °C ... 60 °C
Ambient temperature	-5 °C ... 60 °C
Product weight	13.8 g
Pneumatic connection 1	Prepared for cartridge
Note on materials	Free of copper and PTFE RoHS-compliant
Housing material	PA-reinforced