


Vacuum cup without connector ESV-30-BS

Part number: 191059

FESTO

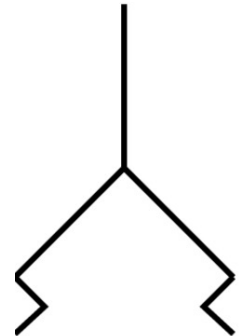

Data sheet

Feature	Value
Suction cup height compensation	8 mm
Min. workpiece radius	80 mm
Suction cup diameter	30 mm
Suction cup volume	4.07 cm ³
Type code	ESV
Connection position	Top
Mounting position	Any
Symbol	00991485
Suction cup shape	Round bellows, 1.5 convolutions
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
For use in the food industry	See supplementary material information
Ambient temperature	-30 °C ... 180 °C
Holding force at nominal operating pressure	26.2 N
Product weight	3.6 g
Color	Transparent
Shore hardness	50 +/- 5
Note on materials	Free of copper and PTFE Contains paint-wetting impairment substances RoHS-compliant
Suction cup material	VMQ (silicone)