


Non return valve VBNF-LBA-G14-Q8

Part number: 1927027

FESTO

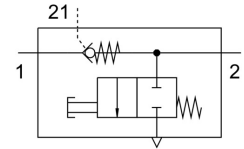

Data sheet

Feature	Value
Type code	VBNF
Valve function	Unlockable non-return function
Selection of additional function	Manual exhaust
Pneumatic connection 1	QS-8
Pneumatic connection 2	G1/4
Pilot air port 21	QS-8
Type of mounting	Screw-in
Operating pressure	0.2 bar ... 10 bar
Pilot pressure	2 bar ... 10 bar
Ambient temperature	-10 °C ... 60 °C
Housing material	PBT
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Mounting position	Any
Actuation type, piloted non-return function	Pneumatic
Manual exhaust function	Non-detenting
Symbol	00991957
Rotatability	360 deg/continuous swiveling not permissible
Operating pressure for entire temperature range	0.2 bar ... 10 bar
Standard flow rate 1->2 (6-0)	1100 l/min
Standard nominal flow rate 1->2 (6-5)	620 l/min
Switching time off	11 ms
On switching time	8 ms
Explosion prevention and protection	Zone 2 (ATEX) Zone 22 (ATEX)
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Temperature of medium	-10 °C ... 60 °C
Pilot medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Nominal tightening torque	11 Nm
Tolerance for nominal tightening torque	± 20%
Product weight	65.6 g
Covering material	ES-BE
Note on materials	RoHS-compliant
Cover material	PBT
Seals material	NBR
Hollow bolt material	Wrought aluminum alloy

Feature	Value
Releasing ring material	POM