


Connecting cable KMYZ-2-24-10-LED

Part number: 193443

FESTO

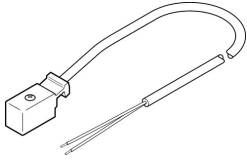

Data sheet

| Feature | Value |
|--|--|
| Type code | KMYZ-2 |
| Switching position indication | LED |
| Type of mounting | On air solenoid valve with self-tapping screw |
| Mounting position | Any |
| Product weight | 170 g |
| Electrical connection | 2-pin/2-wire Angled socket/cable Rectangular design/open end |
| Nominal operating voltage DC | 24 V |
| Current rating at 40°C | 1 A |
| Protective earth connection | Not available |
| Cable length | 10 m |
| Cable characteristic | Standard |
| Cable diameter | 3.4 mm |
| Cable design | 2 x 0.25 mm ² |
| Degree of protection | IP65 |
| Ambient temperature | -10 °C ... 50 °C |
| CE marking (see declaration of conformity) | As per EU RoHS directive |
| Note on materials | RoHS-compliant |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress |
| Material of cable sheath | TPE-U(PUR) |
| Housing material | PA |
| Material of pin contacts | Bronze |