


# Quick coupling plug KS4-CK-4

Part number: 2150

FESTO

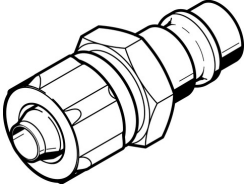

## Data sheet

Feature	Value
Nominal width	2.9 mm
Type code	KS4
Operating pressure for entire temperature range	-0.95 bar ... 12 bar
Standard nominal flow rate	252 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Operation with oil lubrication possible
Corrosion resistance class (CRC)	1 - Low corrosion stress
Ambient temperature	-10 °C ... 60 °C
Product weight	26 g
Pneumatic connection 1	CK-4
Note on materials	RoHS-compliant