


# Sub-base NAUE-1/4-NPT-1-ISO

Part number: 30427

FESTO

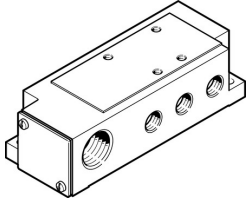

## Data sheet

Feature	Value
Type code	NAUE
Operating pressure	0 bar ... 16 bar
Certification	UL - Recognized (OL)
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Temperature of medium	-10 °C ... 60 °C
Degree of protection	IP65
Ambient temperature	-10 °C ... 60 °C
Type of mounting	With through-hole
Pilot air port 12	1/8 NPTF
Pilot air port 14	1/8 NPTF
Pneumatic connection 1	1/4 NPTF
Pneumatic connection 2	1/4 NPTF
Pneumatic connection 3	1/4 NPTF
Pneumatic connection 4	1/4 NPTF
Pneumatic connection 5	1/4 NPTF