


# Plug socket with cable KMF-1-230AC-2.5

Part number: 30936

FESTO

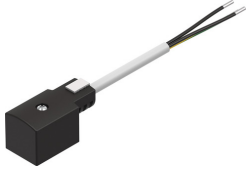

## Data sheet

Feature	Value
Type code	KMF
Type of mounting	On air solenoid valve with M3 central screw
Mounting position	Any
Product weight	170 g
Electrical connection	Socket
Nominal operating voltage AC	230 V
Protective earth connection	Available
Cable length	2.5 m
Cable diameter	6 mm
Cable design	3 x 0.75 mm <sup>2</sup>
Degree of protection	IP67 as per IEC 60529
Ambient temperature	-20 °C ... 80 °C
CE marking (see declaration of conformity)	As per EU RoHS directive As per EU low voltage directive
Material of cable sheath	PVC
Housing material	PC POM
Material of pin contacts	Bronze