


Non return valve H-1/8-A/I

Part number: 3324

FESTO

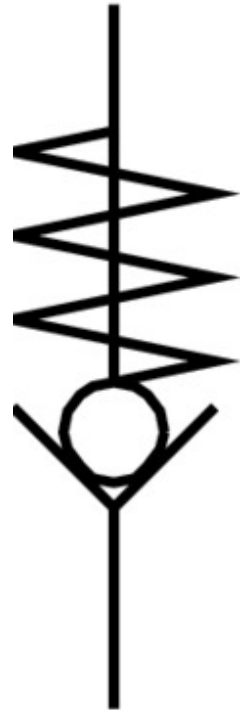

Data sheet

Feature	Value
Type code	H
Valve function	Non-return function
Pneumatic connection 1	G1/8
Pneumatic connection 2	G1/8
Type of mounting	Line installation
Standard nominal flow rate	280 l/min
Operating pressure	0.04 MPa ... 0.8 MPa
Operating pressure	0.4 bar ... 8 bar
Ambient temperature	-10 °C ... 60 °C
Housing material	Brass
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Symbol	00991455
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
LABS conformity	VDMA24364-B2-L
Temperature of medium	-10 °C ... 60 °C
Product weight	21 g
Seals material	NBR