


Clevis flange SNGB-160

Part number: 34547

FESTO

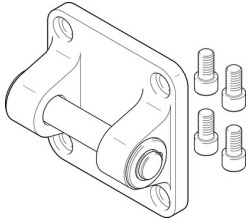

Data sheet

Feature	Value
Size	160
Type code	SNGB
Based on norm	ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS conformity	VDMA24364-B2-L
Ambient temperature	-40 °C ... 90 °C
Product weight	3445 g
Note on materials	Free of copper and PTFE RoHS-compliant
Mounting material	Die-cast aluminum
Bolt material	Steel Galvanized
Material of bearing	Polymer
Disc material	Steel, galvanized
Material of screws	Steel Galvanized
Fuse material	Spring steel, galvanized