


# Vacuum suction cup VAS-100-1/4-NBR

Part number: 34586

FESTO

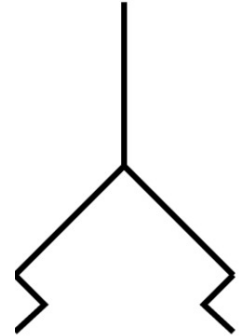

## Data sheet

Feature	Value
Nominal width	4 mm
Suction cup diameter	100 mm
Effective suction cup diameter	85 mm
Type code	VAS
Connection position	Top
Symbol	00991485
Suction cup shape	Round, flat
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
Ambient temperature	-20 °C ... 80 °C
Breakaway force at 70% vacuum	397 N
Holding force at nominal operating pressure	397 N
Mounting thread	G $\frac{1}{4}$
Suction cup mounting	G 1/4
Vacuum connection	G1/4
Color	Black
Shore hardness	70 +/- 5
Material of screwed trunnion	Die-cast zinc
Note on materials	RoHS-compliant
Suction cup material	NBR