
 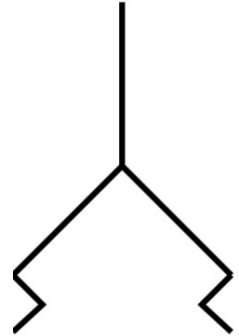


Vacuum suction cup VAS-8-M5-NBR

FESTO

Part number: 34588



Data sheet

| Feature | Value |
|---|---|
| Nominal width | 2 mm |
| Suction cup diameter | 8 mm |
| Effective suction cup diameter | 5.5 mm |
| Type code | VAS |
| Connection position | Top |
| Symbol | 00991485 |
| Suction cup shape | Round, flat |
| Operating medium | Atmospheric air based on ISO 8573-1:2010 [7::-] |
| Ambient temperature | -20 °C ... 80 °C |
| Breakaway force at 70% vacuum | 1.6 N |
| Holding force at nominal operating pressure | 1.6 N |
| Mounting thread | M5 |
| Suction cup mounting | M5 |
| Vacuum connection | M5 |
| Color | Black |
| Shore hardness | 60 +/- 5 |
| Material of screwed trunnion | Brass |
| Note on materials | RoHS-compliant |
| Suction cup material | NBR |