


# Piloted non return valve HGL-3/8-NPT

Part number: 34879

FESTO

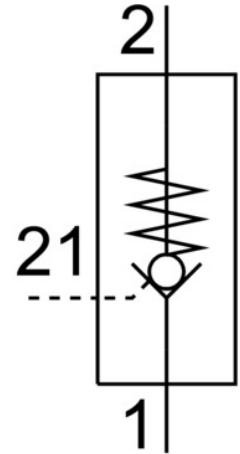

## Data sheet

Feature	Value
Type code	HGL
Valve function	Unlockable non-return function
Pneumatic connection 1	3/8 NPT
Pneumatic connection 2	3/8 NPT
Type of mounting	Screw-in
Standard nominal flow rate	0 l/min ... 900 l/min
Operating pressure	0.02 MPa ... 1 MPa
Operating pressure	0.2 bar ... 10 bar
Pilot pressure MPa	0.12 MPa ... 1 MPa
Pilot pressure	1.2 bar ... 10 bar
Pilot pressure psi	17.4 psi ... 145 psi
Ambient temperature	-20 °C ... 80 °C
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Symbol	00991456
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Temperature of medium	-20 °C ... 80 °C
Note on materials	RoHS-compliant