
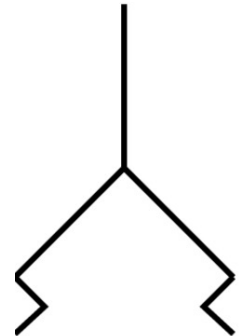


Vacuum suction cup VASB-100-1/4-NBR

Part number: 35416

FESTO

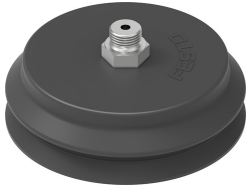

Data sheet

| Feature | Value |
|---------------------------------------------|-------------------------------------------------|
| Nominal width | 4 mm |
| Suction cup diameter | 100 mm |
| Effective suction cup diameter | 85 mm |
| Type code | VASB |
| Connection position | Top |
| Symbol | 00991485 |
| Suction cup shape | Round bellows, 1.5 convolutions |
| Operating medium | Atmospheric air based on ISO 8573-1:2010 [7::-] |
| Ambient temperature | -20 °C ... 80 °C |
| Breakaway force at 70% vacuum | 397 N |
| Holding force at nominal operating pressure | 397 N |
| Mounting thread | G1/4 |
| Suction cup mounting | G 1/4 |
| Vacuum connection | G1/4 |
| Color | Black |
| Shore hardness | 60 +/- 5 |
| Material of screwed trunnion | Die-cast zinc |
| Note on materials | RoHS-compliant |
| Suction cup material | NBR |