


Intermediate pressure regulator plate LR-ZP-A/B-D-3

Part number: 35429

FESTO

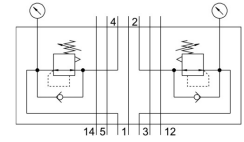

Data sheet

Feature	Value
Type code	LR
Based on norm	ISO 5599-1
Integrated function	Pressure regulator
Structural design	Piston
Symbol	00991580
Pressure regulation range	0.5 bar ... 12 bar
Inlet pressure 1	≤14 bar
Certification	UL - Recognized (OL)
Product weight	1770 g
Note on materials	Contains paint-wetting impairment substances RoHS-compliant
Seals material	NBR
Housing material	Die-cast aluminum Steel