


PE converter PE-1000

Part number: 3719

FESTO

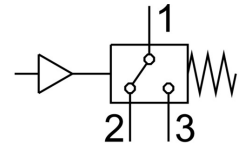

Data sheet

Feature	Value
Type code	PE
Symbol	00991470
CE marking (see declaration of conformity)	As per EU low voltage directive
Measured variable	Relative pressure
Method of measurement	Pneumatic/electric pressure transducer
Operating pressure	0 bar ... 1 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Ambient temperature	-10 °C ... 50 °C
Switching element function	Changeover switch
Switch-on point	0.05 bar
Switch-off point	0.05 bar
Max. switching output voltage AC	250 V
Max. switching output voltage DC	250 V
Cable length	1 m
Type of mounting	With through-hole
Mounting position	Any
Pneumatic connection	M5
Degree of protection	IP62