


# Pneumatic valve A-5-1/4

Part number: 4436

FESTO

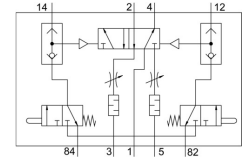

## Data sheet

Feature	Value
Valve function	5/2, bistable
Standard nominal flow rate	700 l/min
Pneumatic working port	G1/4
Operating pressure	0 bar ... 10 bar
Structural design	Piston gate valve
Nominal width	7 mm
Type code	A
Symbol	00991651
Pilot pressure	2 bar ... 10 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Operation with oil lubrication required
Ambient temperature	-10 °C ... 60 °C
Product weight	770 g
Type of mounting	With through-hole
Pneumatic connection 1	G1/4
Pneumatic connection 2	G1/4
Pneumatic connection 3	G1/4
Pneumatic connection 4	G1/4
Pneumatic connection 5	G1/4
Housing material	Aluminum