 



Pneumatic valve VL-5/4-1/4

Part number: 4574

FESTO

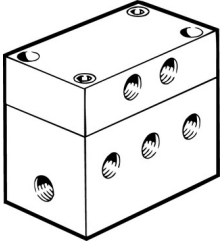

Data sheet

Feature	Value
Valve function	5/4 closed
Pneumatic working port	G1/4
Operating pressure	0 MPa ... 1 MPa
Operating pressure	0 bar ... 10 bar
Type code	VL
Symbol	00991392
Ambient temperature	-10 °C ... 60 °C
Product weight	800 g
Pneumatic connection 1	G1/4
Pneumatic connection 2	G $\frac{1}{4}$
Pneumatic connection 3	G1/4
Pneumatic connection 4	G1/4
Pneumatic connection 5	G1/4