 



Air solenoid valve MC-5/4-1/2

Part number: 4861

FESTO

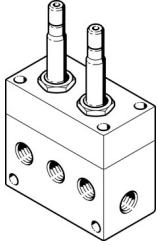

Data sheet

Feature	Value
Valve function	5/4 closed
Actuation type	Electrical
Pneumatic working port	G1/2
Operating pressure	0.2 MPa ... 1 MPa
Operating pressure	2 bar ... 10 bar
Structural design	Plate seat
Reset method	Mechanical spring
Type code	MC
Sealing principle	Soft
Manual override	None
Type of control	Pilot-controlled
Symbol	00991157
Pneumatic connection 1	G1/2
Pneumatic connection 2	G1/2
Pneumatic connection 3	G1/2
Pneumatic connection 4	G1/2
Pneumatic connection 5	G1/2