


Sub-base-SET MS12-AGH

Part number: 537137

FESTO

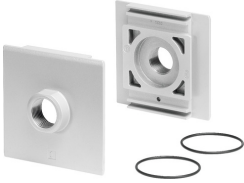

Data sheet

Feature	Value
Size	12
Type code	MS12-AGH
Series	MS
Mounting position	Any
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-10 °C ... 60 °C
Temperature of medium	-10 °C ... 60 °C
Product weight	1300 g
Pneumatic connection 1	G1 1/2
Pneumatic connection 2	G1 1/2
Note on materials	Free of copper and PTFE RoHS-compliant
Material of sub-base	Die-cast aluminum
Seals material	NBR