


Clevis flange SNCL-12

Part number: 537790

FESTO

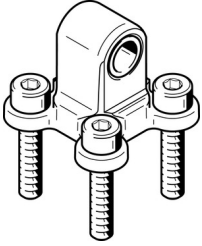

Data sheet

Feature	Value
Size	12
Type code	SNCL
Based on norm	ISO 21287
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Ambient temperature	-40 °C ... 90 °C
Product weight	20 g
Note on materials	Free of copper and PTFE RoHS-compliant
Mounting material	Wrought aluminum alloy
Material of bearing	Polymer
Material of screws	Steel Galvanized