
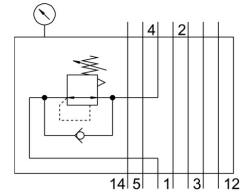


Regulator plate VABF-S4-1-R3C2-C-10

Part number: 540158

FESTO

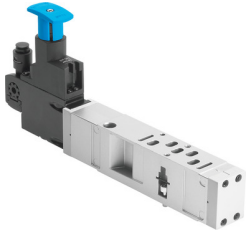

Data sheet

Feature	Value
Width	26 mm
Type code	VABF
Based on norm	ISO 15407-2
Mounting position	Any
Controller function	Outlet pressure constant With secondary exhausting
Symbol	00991579
Optional pressure gauge	Possible
Operating pressure	1 MPa
Operating pressure	10 bar
Pressure regulation range	2 bar ... 10 bar
Inlet pressure 1	0,5 bar ... 10 bar
CE marking (see declaration of conformity)	As per EU low voltage directive
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	0 - No corrosion stress
Degree of protection	IP65 NEMA 4
Pilot medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Ambient temperature	-5 °C ... 50 °C
Product weight	448 g
Vertical stacking mounting type	On manifold sub-base On individual sub-base
Pressure gauge connection	With retaining clamp
Material of operator panel	PA
Controller housing material	Die-cast aluminum