


# Ball valve actuator unit VZPR-BPD-22-R12

Part number: 540512

FESTO

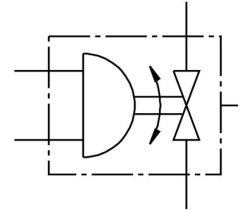

## Data sheet

Feature	Value
Type code	VZPR
Structural design	2-way ball valve Quarter turn actuator
Actuation type	Electrical Pneumatic
Mounting position	Any
Type of mounting	CNOMO With internal thread
Fitting connection	Rp1/2
Switching position indication	Knob direction = flow direction
Nominal width DN	15
Operating pressure of actuator	1 bar ... 8.4 bar
Nominal pressure of fitting PN	40
Symbol	00991921
Temperature of medium	-20 °C ... 150 °C
Ambient temperature	-20 °C ... 80 °C
Note on materials	Contains paint-wetting impairment substances
Product weight	1200 g
Corrosion resistance class (CRC)	1 - Low corrosion stress