


Ball valve actuator unit VZPR-BPD-22-R34

Part number: 540513

FESTO

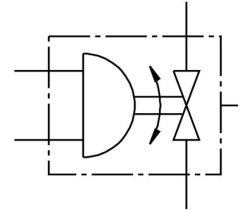

Data sheet

| Feature | Value |
|----------------------------------|----------------------------------------------|
| Type code | VZPR |
| Structural design | 2-way ball valve Quarter turn actuator |
| Actuation type | Electrical Pneumatic |
| Mounting position | Any |
| Type of mounting | CNOMO With internal thread |
| Fitting connection | Rp3/4 |
| Switching position indication | Knob direction = flow direction |
| Nominal width DN | 20 |
| Operating pressure of actuator | 1 bar ... 8.4 bar |
| Nominal pressure of fitting PN | 40 |
| Symbol | 00991921 |
| Temperature of medium | -20 °C ... 150 °C |
| Ambient temperature | -20 °C ... 80 °C |
| Note on materials | Contains paint-wetting impairment substances |
| Product weight | 1500 g |
| Corrosion resistance class (CRC) | 1 - Low corrosion stress |