


# Sub-base VABS-S4-2S-G18-R3

Part number: 541064

FESTO

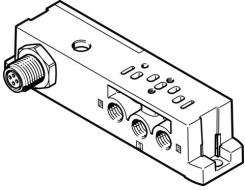

## Data sheet

Feature	Value
Width	18 mm
Type code	VABS
Based on norm	ISO 15407-2
Mounting position	Any
Pilot air supply port	External
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
DC operating voltage range	24 V
Surge resistance	0.8 kV
Current rating at 40°C	2 A
Contamination level	3
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	0 - No corrosion stress
Degree of protection	IP65 NEMA 4 In mounted state
Ambient temperature	-5 °C ... 50 °C
Product weight	192 g
Type of mounting	With through-hole as per ISO 15407-2
Note on materials	RoHS-compliant
Material of sub-base	Die-cast aluminum