


# Sub-base VABS-S4-2S-N18-B-K2

Part number: 541068

FESTO

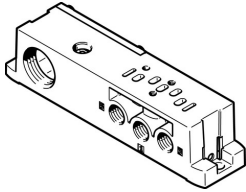

## Data sheet

Feature	Value
Width	18 mm
Type code	VABS
Based on norm	ISO 15407-2
Mounting position	Any
Pilot air supply port	Internal
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Operating voltage range AC	110 V
DC operating voltage range	24 V
Surge resistance	4 kV
Current rating at 40°C	2 A
Contamination level	3
CE marking (see declaration of conformity)	As per EU low voltage directive
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	0 - No corrosion stress
Degree of protection	IP65 NEMA 4 In mounted state
Ambient temperature	-5 °C ... 50 °C
Product weight	192 g
Type of mounting	With through-hole as per ISO 15407-2
Note on materials	RoHS-compliant
Material of sub-base	Die-cast aluminum