


Branching module MS12-FRM-G

Part number: 541681

FESTO

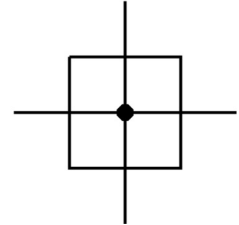

Data sheet

Feature	Value
Type code	MS12-FRM
Mounting position	Any
Structural design	Branching module
Symbol	00991510
Operating pressure	0 bar ... 20 bar
Standard nominal flow rate in main flow direction 1 -> 2	25000 l/min ... 42000 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [:-:-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-10 °C ... 60 °C
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	3000 g
Pneumatic connection 1	Battery module
Pneumatic connection 2	Battery module
Pneumatic connection 3	G2
Pneumatic connection 4	G1
Note on materials	Free of copper and PTFE
Housing material	Die-cast aluminum