
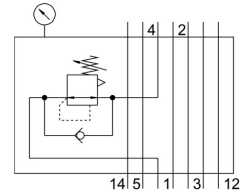


# Regulator plate VABF-S3-2-R3C2-C-10

Part number: 543530

FESTO

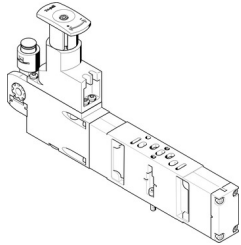

## Data sheet

Feature	Value
Width	18 mm
Type code	VABF
Based on norm	ISO 15407-1
Mounting position	Any
Pneumatic vertical stacking	Pressure regulator for 4
Controller function	Outlet pressure constant With secondary exhausting
Symbol	00991579
Optional pressure gauge	Possible
Pressure regulation range MPa	0.2 MPa ... 0.85 MPa
Pressure regulation range	2 bar ... 8.5 bar
Pressure regulation range psi	29 psi ... 123.25 psi
Inlet pressure 1	0.5 bar ... 10 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	0 - No corrosion stress
Degree of protection	IP65 NEMA 4
Ambient temperature	-5 °C ... 50 °C
Product weight	245 g
Vertical stacking mounting type	On manifold sub-base On individual sub-base
Pressure gauge connection	With retaining clamp
Note on materials	RoHS-compliant
Material of operator panel	PA
Controller housing material	Die-cast aluminum