


Basic valve LF-D-MINI-A-U

Part number: 546429

FESTO

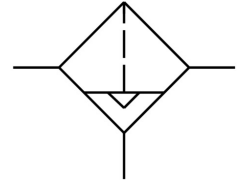

Data sheet

Feature	Value
Size	Mini
Type code	LF
Series	D
Mounting position	Vertical +/- 5°
Grade of filtration	40 µm
Condensate drain	Fully automatic
Structural design	Sinter filter with centrifugal separator
Max. condensate volume	21.991 ml
Bowl guard	Metal bowl guard
Symbol	00991520
Operating pressure	1.931 bar ... 12.411 bar
Standard nominal flow rate	4449.15 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:9:-] Inert gas
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-10 °C ... 60 °C
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [7:8:4] Inert gas
Temperature of medium	5 °C ... 60 °C
Ambient temperature	5 °C ... 60 °C
Product weight	248.062 g
Type of mounting	Line installation With accessories
Note on materials	RoHS-compliant
Compressed air filter material	PE
Housing material	Die-cast zinc
Material of bowl	PC