


Basic valve LOE-D-MINI-U

Part number: 546431

FESTO

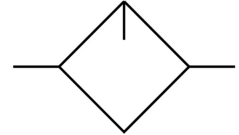

Data sheet

| Feature | Value |
|--|--|
| Size | Mini |
| Type code | LOE |
| Series | D |
| Mounting position | Vertical +/- 5° |
| Structural design | Proportional standard oil mist lubricator |
| Max. oil capacity | 44.982 cm ³ |
| Bowl guard | Metal bowl guard |
| Symbol | 00991532 |
| Operating pressure | 0 bar ... 16.547 bar |
| Standard nominal flow rate | 5783.9 l/min |
| Operating medium | Compressed air as per ISO 8573-1:2010 [7:4:4] Inert gas |
| Information on operating and pilot media | Operation with oil lubrication not possible |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress |
| Storage temperature | -10 °C ... 60 °C |
| Air quality class at the output | Compressed air as per ISO 8573-1:2010 [7:4:-] Inert gas |
| Temperature of medium | -10 °C ... 60 °C |
| Ambient temperature | -10 °C ... 60 °C |
| Product weight | 267.908 g |
| Type of mounting | With accessories |
| Note on materials | RoHS-compliant |