


# Basic valve LFMA-D-MAXI-U

Part number: 546447

FESTO

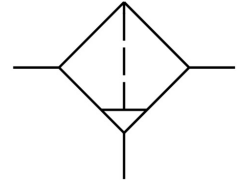

## Data sheet

Feature	Value
Series	D
Size	Maxi
Type code	LFMA
Structural design	Fiber filter
Grade of filtration	0.01 µm
Condensate drain	Manually rotating
Symbol	00991519
Operating pressure	0.951 bar ... 16.547 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [6:8:4] Inert gas
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [1:7:2] Inert gas
Filter efficiency	99.9999 %
Bowl guard	Metal bowl guard
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Temperature of medium	1 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Residual oil content	0.01 mg/m <sup>3</sup>
Type of mounting	Optionally: Line installation With accessories
Mounting position	Vertical +/- 5°
Housing material	Die-cast zinc
Compressed air filter material	Borosilicate fiber
Material of bowl	PC
Note on materials	Free of copper and PTFE RoHS-compliant
Product weight	1190.7 g