


Basic valve LF-D-5M-MAXI-A-U

Part number: 546467

FESTO

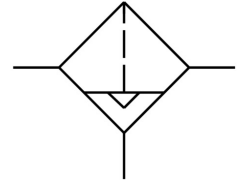

Data sheet

Feature	Value
Size	Maxi
Type code	LF
Series	D
Mounting position	Vertical +/- 5°
Grade of filtration	5 µm
Condensate drain	Fully automatic
Structural design	Sinter filter with centrifugal separator
Max. condensate volume	79.968 ml
Bowl guard	Metal bowl guard
Symbol	00991520
Operating pressure	1.931 bar ... 12.411 bar
Standard nominal flow rate	16461.86 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:9:-] Inert gas
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-10 °C ... 60 °C
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [6:8:4] Inert gas
Temperature of medium	5 °C ... 60 °C
Ambient temperature	5 °C ... 60 °C
Product weight	1329.615 g
Type of mounting	Line installation With accessories
Note on materials	RoHS-compliant
Compressed air filter material	PE
Housing material	Die-cast zinc
Material of bowl	PC