


Vacuum filter VAF-DB-1/4

Part number: 547261

FESTO

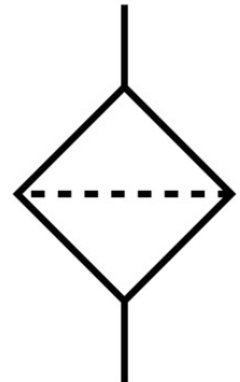

Data sheet

Feature	Value
Type code	VAF
Mounting position	Vertical
Grade of filtration	80 µm
Symbol	00991483
Operating pressure	-0.95 bar ... 0 bar
Information on operating pressure	Only for use in open vacuum systems
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:]
Ambient temperature	-5 °C ... 50 °C
Max. tightening torque	8.7 Nm
Product weight	71 g
Type of mounting	Line installation With wall/surface bracket
Pneumatic connection	G1/4
Vacuum connection	G1/4
Note on materials	Contains paint-wetting impairment substances RoHS-compliant
Seals material	NBR
Compressed air filter material	PE
Housing material	PP-reinforced
Material of bowl	PA
Ejector pulse suitability	≤7 bar