


Pneumatic shock absorber DYSW-4-6-Y1F

Part number: 548070

FESTO

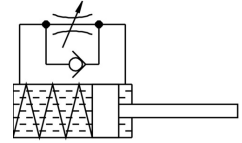

Data sheet

Feature	Value
Size	4
Stroke	6 mm
Type code	DYSW
Cushioning	Self-adjusting Soft characteristic curve
Mounting position	Any
Position sensing	None
Symbol	00991495
Max. impact velocity	2 m/s
Reset time at room temperature	0.2 s
Reset time at min. ambient temperature	1 s
Mode of operation	Single-acting Pushing
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Ambient temperature	-10 °C ... 80 °C
Cushioning length	6 mm
Max. stop force	100 N
Max. energy absorption per stroke	0.8 J
Max. energy absorption per hour	7000 J
Max. residual energy	0.006 J
Resetting force	0.7 N
Product weight	6 g
Type of mounting	With lock nut
Note on materials	Free of copper and PTFE RoHS-compliant
Seals material	NBR
Housing material	High-alloy steel
Piston rod material	High-alloy steel